

KINGSTATE'S IP- rating diaphragm Speakers

KDMG20008C-10FW3 KDMG28004X-20WF KDMG30008R-10FW8
KDSG15008M-05WF KDSG15008X-10WF KDSG151108X-07PF KDSG20008R-10W
TRFG50008C-30F

KINGSTATE announced new speakers with diaphragm with IP ratings. The diaphragm of these speaker are IP rating.

P/N	IP	DIMENSION	SPEC DESCRIPTION
KDMG20008C-10FW3	IP65	OD20xT3.2mm	Rated 1W, 8Ω FO: 950Hz, 87dB/0.1W/0.1M Fo-10KHz
KDMG28004X-20WF	IP55	OD28xT4.4mm	Rated 2W, 4Ω FO: 450Hz, 92dB/1.0W/0.1M Fo-8KHz
KDMG30008R-10FW8	IP55	OD30xT5.8mm	Rated 1W, 8Ω FO: 500Hz, 88dB/0.1W/0.1M Fo-20KHz
KDSG15008M-05WF	IP54	OD15xT3.8mm	Rated 0.5W, 8Ω FO: 880Hz, 88dB/0.1W/0.1M Fo-20KHz
KDSG15008X-10WF	IP55	OD15xT4.0mm	Rated 1.0W, 8Ω FO: 1,000Hz, 95dB/1.0W/0.1M Fo-20KHz
KDSG151108X-07PF	IP67	L15xW11xT3.5mm	Rated 0.7W, 8Ω FO: 800Hz, 83dB/0.1W/0.1M Fo-20KHz
KDSG20008R-10W	IP67	OD20xT5.5mm	Rated 1W, 8Ω FO: 1,000Hz, 98dB/1.0W/0.1M Fo-20KHz
TRFG50008C-30F	IPX5	OD50xT17mm	Rated 3W, 8Ω FO: 600Hz, 88dB/0.1W/0.1M Fo-5KHz

So client can design a panel and fit the speaker into the baffle and diaphragm open to the space. The bottom water will be wrapped and protected in client housing desing.


Feature:

- Front – Diaphragm with IP rating.
- High SPL
- Good Sound Quality
- Wire Length and Connectors subject to customization.

Application:

- Consumer Electronics
- Industrial Equipment
- Home Appliances
- Medical Electronics
- Information System

Speaker IP Diaphragm

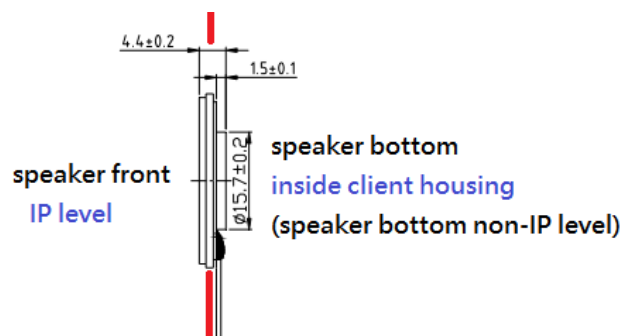

For further information:

Kingstate Electronics Corporation
 E-mail: aliciachu@kingstate.com.tw
 Tel: +886-2-2809-5651 #1213
 Website: www.kingstate.com.tw