









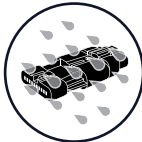

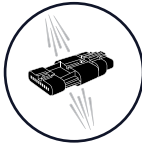
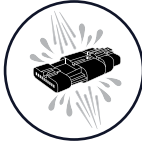
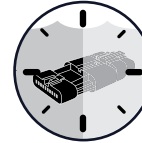

Ingress Protection (IP) Ratings >



SOLIDS

- 1**  Protected against a solid object greater than 50.00 mm such as a hand
- 2**  Protected against a solid object greater than 12.50mm such as a finger
- 3**  Protected against a solid object greater than 2.50mm such as a screwdriver
- 4**  Protected against a solid object greater than 1.00mm such as a wire
- 5**  Dust protected; limited ingress of dust permitted; two to eight hours
- 6**  Dust tight; no ingress of dust; two to eight hours

WATER

- 1**  Protected against vertical falling drops of water; limited ingress permitted
- 2**  Protected against falling drops of water with enclosure tilted up to 15°; limited water permitted
- 3**  Protected against sprays of water up to 60° from the vertical; limited water permitted for three minutes
- 4**  Protected against water splashed from all directions; limited water permitted
- 5**  Protected against currents of water; limited water permitted
- 6**  Protected against powerful jets of water; limited ingress permitted
- 7**  Can be immersed in up to 1.0 meter of water for up to 30 minutes
- 8**  Can be immersed in up to 1.5 meters of water for up to 30 minutes

