



life.augmented

STM32H7 series Powered by Arm[®] Cortex[®]-M7 & -M4 releasing your creativity



presented by
EBVElektronik
| An Avnet Company |



STM32H7

high performance

High-performance MCUs with Arm® Cortex®-M7 core and Arm® Cortex®-M4

The STM32H7 series offer the performance of the Arm® Cortex®-M7 core running up to 550 MHz and add a 240 MHz Arm® Cortex®-M4 core in dual-core lines. Combined with a smart architecture based on a multi-power domain, developers can always use the best configuration to optimize data transfers and CPU load while minding the power budget.

With its embedded hardware accelerators and its extensive digital and analog peripherals, the feature-rich STM32H7 is ideal for industrial environments where fast reaction time is essential. The HMI components (graphic and audio support) allow the device to provide an outstanding user-experience.

CORE, MEMORIES AND ACCELERATION

- Arm® Cortex®-M7 core up to 480 MHz and Arm® Cortex®-M4* core up to 240 MHz in dual core variants
- Arm® Cortex®-M7 core up to 550 MHz in single core variants
- Up to 32 KB + 32 KB I/D L1 Cache
- Double-precision FPU
- 4 x DMA controllers
- 128 KB up to 2 MB dual bank Flash and up to 1.4 MB RAM

Note: * only in STM32H745, STM32H755, STM32H747 and STM32H757

CONNECTIVITY

- Up to 2 x USB 2.0 OTG FS/HS
- USART, UART, SPI, and I²C
- 2 x CAN (1 x FD and 1 x TT/FD)
- Ethernet MAC
- FMC, Quad-SPI and Dual Octal-SPI
- 2 x SDMMC

AUDIO

- 3 x I²S + audio PLL
- 4 x SAI
- 2 x 12-bit DAC
- SPDIF-RX


GRAPHICS

- LCD TFT controller
- JPEG Codec
- Chrom-ART Accelerator™
- Chrom-GRC™

OTHER

- Optional crypto
- DFSDM
- 16- and 32-bit timers
- Up to 3x ADCs with 16-bit max. resolution (up to 3.6 MSPS)
- 1 x ADC with 12-bit max. resolution (up to 5 MSPS)
- Analog (comp, AOP)
- Power supply 1.7V to 3.6V down to 1.62V in regulator bypass mode
- Up to 140 °C supported as maximum junction temperature

Two powerful cores supported by a robust architecture

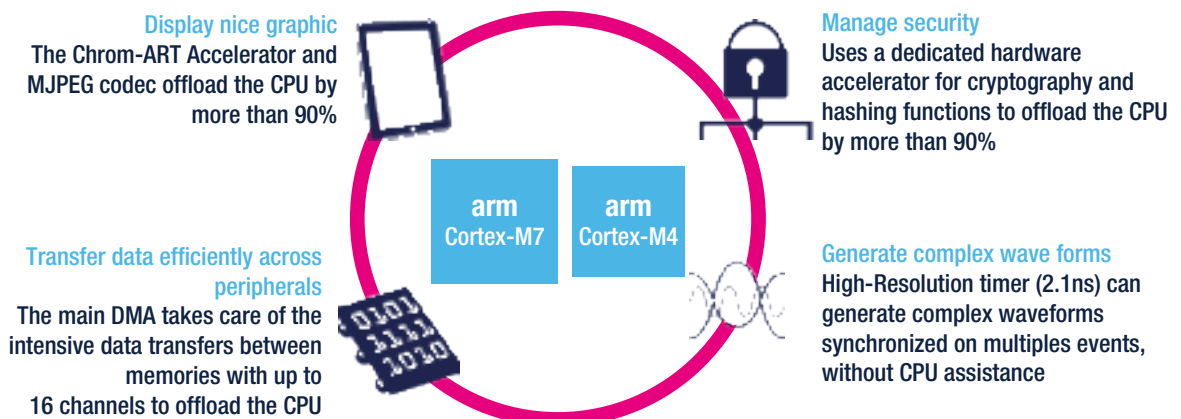


UP TO SEVEN LINES FOR MORE VERSATILITY

CORE, MEMORIES AND ACCELERATION <ul style="list-style-type: none"> Single-core Cortex-M7 up to 550 MHz Dual-core Cortex-M7 480 MHz and Cortex-M4 240 MHz Flash and RAM acceleration SP-FPU and DP-FPU 4 x DMA Mathematics (only H723/733/725/735/730) CONNECTIVITY <ul style="list-style-type: none"> Up to 2 x USB2.0 OTG FS/HS 2 x SDMMC USART, UART, SPI, I²C Up to 3 x CAN (2 x FD and 1 x TT) HDMI-CEC FMC, Dual-mode Quad-SPI or 2 x Octo-SPI Camera I/F AUDIO <ul style="list-style-type: none"> 3 x I²S + audio PLL 4 x SAI 2 x 12-bit DAC SPDIF-RX GRAPHIC <ul style="list-style-type: none"> Chrom-ART Accelerator™ OTHER <ul style="list-style-type: none"> Crypto/Hash option (except H742)¹ Security services option (except H742) TRNG DFSDM 16- and 32-bit timers HRTimer (except STM32H7A/H7B/H7B0/H723/H725/H730/H733/H735) Up to 3 x 16-bit ADC (up to 3.6 MSPS) Analog (compt,AOP) Voltage range 1.62 to 3.6 V (except 100-pin and VFQFPN68 packages : 1.71 to 3.6 V) Multi-power domains -40°C up to 105°C ambient -40°C up to 125°C ambient² 	Product line	f _{CPU} (MHz)	Dual-Bank Flash memory (bytes)	RAM (bytes)	OctoSPI & OTFDEC ³	Ethernet	Graphic	Power supply	Stop mode (typical) / RAM retention	
	Dual-core lines									
	STM32H747/757¹	480 + 240	Up to 2 Mbytes	1 Mbyte (incl.128 Kbytes DTCM + 64 Kbytes ITCM + 64 Kbytes backup ¹) + 4 Kbytes backup ²			•	TFT-LCD JPEG codec MIPI-DSI	SMPS + LDO	360 µA / 1MB 250 µA / 768KB
	STM32H745/755¹	480 + 240	Up to 2 Mbytes	1 Mbyte (incl.128 Kbytes DTCM + 64 Kbytes ITCM + 64 Kbytes backup ¹) + 4 Kbytes backup ²			•	TFT-LCD JPEG codec	SMPS + LDO	360 µA / 1MB 250 µA / 768KB
	Single-core lines									
	STM32H7A3/7B3¹	280	Up to 2 Mbytes	1,4MB (incl.128K DTCM, 64K ITCM, 1184K+SRAM, 4K backup)			•	TFT-LCD JPEG codec Chrom-GRC	SMPS + LDO	32 µA / 1.4MB 28 µA / 32KB
	STM32H743/753¹	480	Up to 2 Mbytes	1 Mbyte (incl.128 Kbytes DTCM + 64 Kbytes ITCM + 64 Kbytes backup ¹) + 4 Kbytes backup ²			•	TFT-LCD JPEG codec	LDO	1270 µA / 1MB 910 µA / 768KB
	STM32H742	480	Up to 2 Mbytes	692 Kbytes (incl.128 Kbytes DTCM + 64 Kbytes ITCM + 16 Kbytes backup ¹) + 4 Kbytes backup ²			•		LDO	1270 µA / 692KB 910 µA / 704KB
	STM32H725/735³	550	Up to 1 Mbyte	564KB (incl.128K DTCM, 432KB Syst + 4K bckup)		•	•	TFT-LCD	SMPS ⁴ + LDO	200 µA / 564KB
	STM32H723/733³	550	Up to 1 Mbyte	564KB (incl.128K DTCM, 432KB Syst + 4K bckup)		•	•	TFT-LCD	LDO	520 µA / 564KB
Value line										
STM32H7B0	280	128 Kbytes	1,4MB (incl.128K DTCM, 64K ITCM, 1184K+SRAM, 4K backup)			•	TFT-LCD JPEG codec Chrom-GRC	SMPS + LDO	32 µA / 1.4MB 28 µA / 32KB	
STM32H750	480	128 Kbytes	1 Mbyte (incl.128 Kbytes DTCM + 64 Kbytes ITCM + 64 Kbytes backup ¹) + 4 Kbytes backup ²			•	TFT-LCD JPEG codec	LDO	1270 µA / 1MB 910 µA / 768KB	
STM32H730	550	128 Kbytes	564KB (incl.128K DTCM, 432KB Syst + 4K bckup)		•	•	TFT-LCD	SMPS ⁴ + LDO	200 µA / 564KB 520 µA / 564KB	

Notes :

- Optional - dedicated CPN, STM32H733, STM32H735, STM32H753, STM32H755, STM32H757, STM32H7B3 for the Crypto Variants
- 125 °C ambient / 140 °C junction. Dedicated part numbers on STM32H725/H735, STM32H745/H755
- Crypto and Security services on CPN : STM32H733, STM32H735 and STM32H730
- SMPS available only on STM32H730Q CPN
- SMPS only on the QFN68 variant (no LDO)

STM32H735 BLOCK DIAGRAM

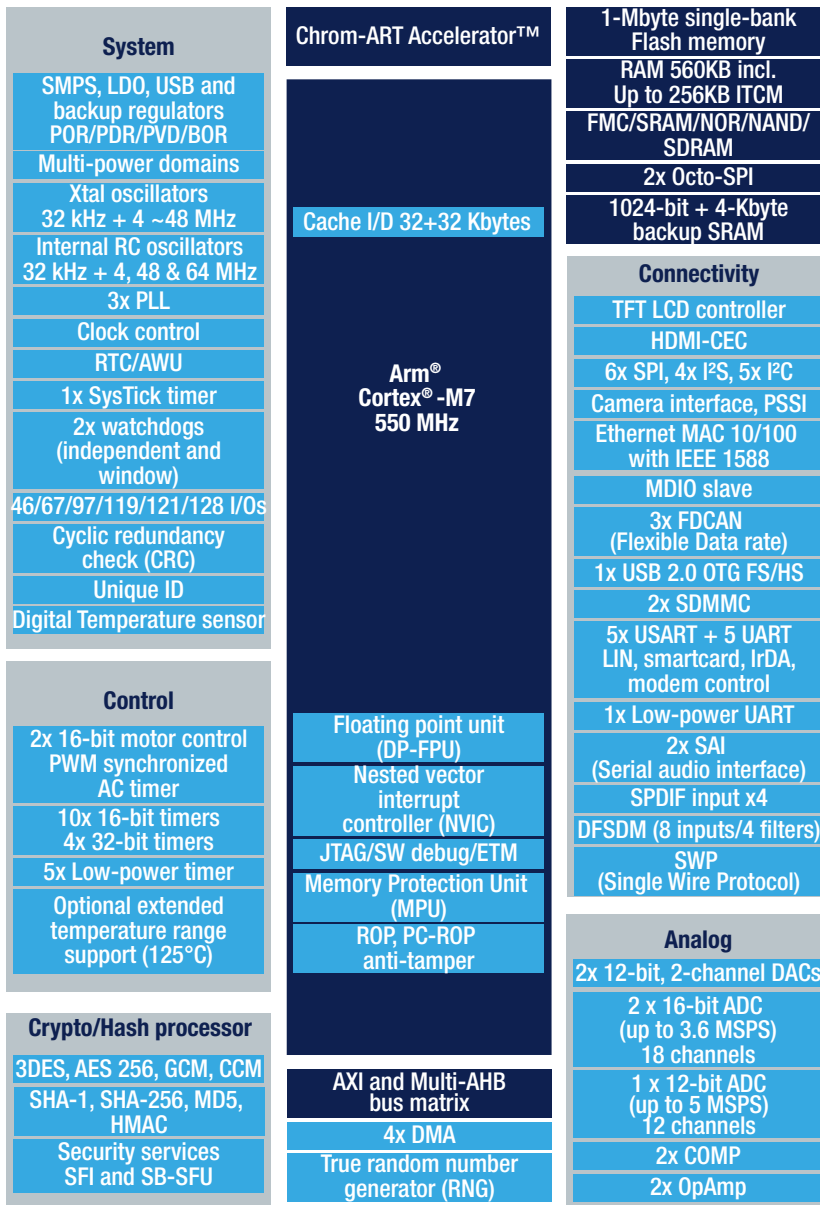

STM32H7 ONLINE TRAINING

www.st.com/stm32h7-online-training




The STM32Trust ecosystem combines knowledge, design tools, and ready-to-use original ST software to build strong cyber-protection into new IoT devices, leveraging industry best-practices. www.st.com/stm32trust



Secure your production flow with Secure Firmware Install (SFI)*

Manage STM32 authentication, firmware decryption and installation

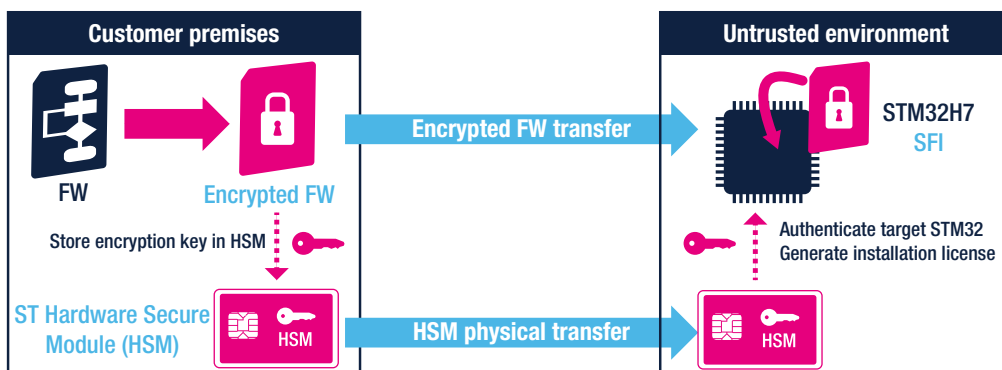

Note: *optional – SFI service available on specific part numbers

STM32H7 ecosystem

HARDWARE TOOLS

www.st.com/stm32hardwaretools

Part numbers	Product Line	Core	SMPS	Crypto-HASH	Display	Ethernet	NOR Serial Flash (Mbits)	SDRAM (Mbits)	HyperRAM™	SRAM (Mbits)	NOR (Mbits)	eMMC (Gbytes)	SDCard (Bbytes)	
Nucleo-144 boards														
	NUCLEO-H723ZG	General-purpose	1	-	No	No	Yes	No	-	-	-	-	-	
	NUCLEO-H743ZI2	General-purpose	1	-	No	No	Yes	No	-	-	-	-	-	
	NUCLEO-H745ZI-Q	Industrial	2	Internal	No	No	Yes	No	-	-	-	-	-	
	NUCLEO-H753ZI	General-purpose	1	-	Yes	No	Yes	No	-	-	-	-	-	
	NUCLEO-H755ZI-Q	Industrial	2	Internal	Yes	No	Yes	No	-	-	-	-	-	
	NUCLEO-H7A3ZI-Q	General-purpose	1	Internal	Yes	No	No	No	-	-	-	-	-	
Discovery kits														
	STM32H735G-DK	Industrial	1	Internal	Yes	4.3" RGB	Yes	1 x 512 Mb Octo-SPI	-	128 Mb	-	-	-	
	STM32H745I-DISCO	Industrial	2	Internal	No	4.3" RGB	Yes	2 x 512 Mb Quad-SPI	128 Mb	-	-	-	4 GB	
	STM32H747I-DISCO	Graphic	2	Internal	No	4" DSI	Yes	2 x 512 Mb Quad-SPI	256 Mb	-	-	-	-	
	STM32H747I-DISCO1	Graphic	2	Internal	No	No	Yes	2 x 512 Mb Quad-SPI	256 Mb	-	-	-	-	
	STM32H750B-DK	Value	1	-	Yes	4.3" RGB	Yes	2 x 512 Mb Quad-SPI	128 Mb	-	-	-	4 GB	
	STM32H7B3I-DK	Graphic	1	Internal	Yes	4.3" RGB	No	1 x 512 Mb Octo-SPI	128 Mb	-	-	-	-	
Evaluation boards														
	STM32H743I-EVAL2	General-purpose	1	-	No	5.7" RGB	Yes	2 x 512 Mb Quad-SPI	256 Mb	-	16 Mb	128 Mb	-	8 GB
	STM32H753I-EVAL2	General-purpose	1	-	Yes	5.7" RGB	Yes	2 x 512 Mb Quad-SPI	256 Mb	-	16 Mb	128 Mb	-	8 GB
	STM32H747I-EVAL	Graphic	2	Internal	No	4" DSI	Yes	2 x 512 Mb Quad-SPI	256 Mb	-	16 Mb	128 Mb	-	8 GB
	STM32H757I-EVAL	Graphic	2	Internal	Yes	4" DSI	Yes	2 x 512 Mb Quad-SPI	256 Mb	-	16 Mb	128 Mb	-	8 GB
	STM32H7B3I-EVAL	Graphic	1	Internal	Yes	7" RGB	No	1 x 512 Mb Octo-SPI	256 Mb	-	16 Mb	128 Mb	-	-

SOFTWARE TOOLS

www.st.com/stm32softwaretools




Note:
- Arm Keil, IAR-EWARM, STM32CubeIDE and aC6 support multi-core debugging



EMBEDDED SOFTWARE

www.st.com/stm32embeddedsoftware

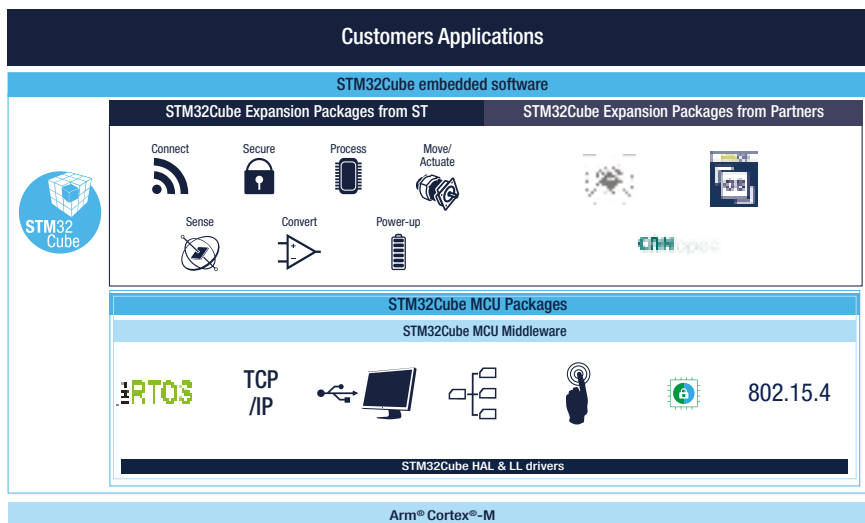

ST COMMUNITY
Ask, learn, share, discuss, and engage with the community of STM32 enthusiasts on community.st.com/stm32

STM32 EDUCATION
Bring your STM32 project to life with the free educational and training resources available on st.com/stm32education

EBV European Headquarters

EBV Elektronik GmbH & Co. KG | DE-85586 Poing | Im Technologiepark 2-8 | Phone: +49 8121 774 0

EBV Regional Offices | Status January 2021

AUSTRIA

1120 Wien
Grünbergstraße 15/1, 4. Stock
Phone: +43 1 89152 0
Fax: +43 1 89152 30

BELGIUM

1831 Diegem
De Kleetlaan 3
Phone: +32 2 716001 0
Fax: +32 2 72081 52

BULGARIA

1505 Sofia
48 Sitnyakovo Blvd., Serdika
offices, 10th floor, Unit 1006
Phone: +359 2 9264 337
Fax: +359 2 9264 133

CZECH REPUBLIC

18600 Prague
Amazon Court, Karolinska 661/4
Phone: +420 2 34091 011
Fax: +420 2 34091 010

DENMARK

8230 Åbyhøj
Ved Lunden 10-12, 1. sal
Phone: +45 8 6250 466
Fax: +45 8 6250 660

ESTONIA

80042 Pärnu
Suur-Jõe 63
Phone: +372 5 8864 446

FINLAND

02240 Espoo
Pihatörmä 1a
Phone: +358 9 2705279 0
Fax: +358 9 27095498

FRANCE

90100 Oulu
Nahkatehtaankatu 2
Phone: +358 8 4152627 0
Fax: +358 8 4152627 5

FRANCE

91300 Massy Cedex (Paris)
Le Copernic bât B
12 rue Jean Bart
Phone: +33 1 644729 29

35510 Cesson Sévigné (Rennes)
35, av. des Peupliers
Phone: +33 2 998300 51
Fax: +33 2 998300 60

67400 Illkirch Graffenstaden
35 Rue Gruninger
Phone: +33 3 904005 92
Fax: +33 3 886511 25

31500 Toulouse
8 chemin de la terrasse
Parc de la plaine
Phone: +33 5 610084 61
Fax: +33 5 610084 74

69693 Venissieux (Lyon)
Parc Club du Moulin à Vent
33, Av. du Dr. Georges Lévy
Phone: +33 4 727802 78
Fax: +33 4 780080 81

GERMANY

85609 Aschheim-Dornach
Einsteinring 1
Phone: +49 89 388 882 0
Fax: +49 89 388 882 020

10553 Berlin
Kaiserin-Augusta-Allee 14
Phone: +49 30 747005 0
Fax: +49 30 747005 55

30938 Burgwedel
Burgdorfer Straße 2
Phone: +49 5139 8087 0
Fax: +49 5139 8087 70

59439 Holzwickede
Wilhelmstraße 1
Phone: +49 2301 94390 0
Fax: +49 2301 94390 30

41564 Kaarst
An der Gümpgesbrücke 7
Phone: +49 2131 9677 0
Fax: +49 2131 9677 30

71229 Leonberg
Neue Ramtelstraße 4
Phone: +49 7152 3009 0
Fax: +49 7152 759 58

90471 Nürnberg
Lina-Ammon-Straße 19B
Phone: +49 911 817669 0
Fax: +49 911 817669 20

04435 Schkeuditz
Frankfurter Straße 2
Phone: +49 34204 4511 0
Fax: +49 34204 4511 99

78048 VS-Villingen
Marie-Curie-Straße 14
Phone: +49 7721 99857 0
Fax: +49 7721 99857 70

65205 Wiesbaden
Borsigstraße 36
Phone: +49 6122 8088 0
Fax: +49 6122 8088 99

HUNGARY

1117 Budapest
Budafoki út 91-93, West Irodaház
Phone: +36 1 43672 29
Fax: +36 1 43672 20

ISRAEL

4581500 Bnei Dror
Tirosh 1
Phone: +972 9 77802 60
Fax: +972 3 76011 15

ITALY

20095 Cusano Milanino (MI)
Via Alessandro Manzoni, 44
Phone: +39 02 660962 90
Fax: +39 02 660170 20

50019 Sesto Fiorentino (FI)
Via Lucchese, 84/B
Phone: +39 05 543693 07
Fax: +39 05 542652 40

41126 Modena (MO)
Via Scaglia Est, 33
Phone: +39 059 292 4211
Fax: +39 059 292 9486

00139 Roma (RM)
Via de Settebagni, 390
Phone: +39 06 4063 665/789
Fax: +39 06 4063 777

35030 Sarmeola di Rubano (PD)
Piazza Adelaide Lonigo, 8/11
Phone: +39 049 89747 01
Fax: +39 049 89747 26

10144 Torino (TO)
Via Treviso, 16
Phone: +39 011 26256 90
Fax: +39 011 26256 91

IRELAND

Fitzwilliam Hall
Fitzwilliam Place
Dublin 2
D02 T292
Phone: +353 1 4097 802
Fax: +353 1 4568 544

NETHERLANDS

Zonnebaan 9
3542 EA Utrecht
Phone: +31 346 5830 10
Fax: +31 346 5830 25

NORWAY

3440 Røyken
Kleiverveien 35
Phone: +47 22 67 17 80
Fax: +47 22 67 17 89

POLAND

80-838 Gdansk
Targ Rybny 11/12
Phone: +48 58 30781 00

P02-676 Warszawa
Postepu 14
Phone: +48 22 209 88 05

50-062 Wrocław
Pl. Solny 16
Phone: +48 71 34229 44
Fax: +48 71 34229 10

PORTUGAL

4400-676 Vila Nova de Gaia Unipessoal
LDA / Edifício Tower Plaza
Rotunda Eng. Edgar Cardoso, 23 - 14ºG
Phone: +351 22 092026 0
Fax: +351 22 092026 1

ROMANIA

020334 Bucharest
4C Gara Herastrau Street
Building B, 2nd Floor - 2nd District
Phone: +40 21 52816 12
Fax: +40 21 52816 01

RUSSIA

620028 Ekaterinburg
Tatischeva Street 49A
Phone: +7 343 31140 4
Fax: +7 343 31140 46

127486 Moscow
Korovinskoye Shosse 10,
Build 2, Off. 28
Phone: +7 495 730317 0
Fax: +7 495 730317 1

197374 St. Petersburg
Atlantic City, Savushkina str 126,
lit B, premises 59-H, office 17-2
Phone: +7 812 635706 3
Fax: +7 812 635706 4

SERBIA

11070 Novi Beograd
Milentija Popovica 5B
Phone: +381 11 40499 01
Fax: +381 11 40499 00

SLOVAKIA

82109 Bratislava
Turcianska 2 Green Point Offices
Phone: +421 2 3211114 1
Fax: +421 2 3211114 0

SLOVENIA

1000 Ljubljana
Dunajska cesta 167
Phone: +386 1 5609 778
Fax: +386 1 5609 877

SOUTH AFRICA

7700 Rondebosch, Cape Town
Belmont Office Park, Belmont Road
1st Floor, Unit 0030
Phone: +27 21 402194 0
Fax: +27 21 4196256

3629 Westville
Forest Square, 11 Derby Place
Suite 4, Bauhinia Building
Phone: +27 31 27926 00
Fax: +27 31 27926 24

2128 Rivonia, Sandton
Johannesburg
33 Riley Road
Pinewood Office Park
Building 13, Ground Floor
Phone: +27 11 23619 00
Fax: +27 11 23619 13

SPAIN

08014 Barcelona
c/ Tarragona 149 - 157 Planta 19 1º
Phone: +34 93 47332 00
Fax: +34 93 47363 89

39005 Santander (Cantabria)
Racing nº 5 bajo
Phone: +34 94 22367 55
Phone: +34 94 23745 81

28760 Tres Cantos (Madrid)
c/ Ronda de Poniente 14 - 2ª planta
Phone: +34 91 80432 56
Fax: +34 91 80441 03

SWEDEN

16440 Kista
Isafjordsgatan 32B, Floor 6
Phone: +46 859 47023 0
Fax: +46 859 47023 1

SWITZERLAND

8953 Dietikon
Bernstrasse 394
Phone: +41 44 74561 61
Fax: +41 44 74561 00

TURKEY

06520 Ankara
Armada Is Merkezi
Eskisehir Yolu No: 6, Kat: 14
Ofis No: 1406, Sogutozu
Phone: +90 312 2956 361
Fax: +90 216 528831 1

34774 Ümraniye / Istanbul
Tatlısu Mahallesi Pakdil Sokak 7
Phone: +90 216 528831 0
Fax: +90 216 528831 1

35580 Izmir
Folkart Towers
Manas Blv. No 39 B Blok
Kat: 31 Ofis: 3121
Phone: +90 232 390 9196
Fax: +90 216 528831 1

UKRAINE

03040 Kiev
Vasilovskaya str. 14
off. 422-423
Phone: +380 44 496222 6
Fax: +380 44 496222 7

UNITED KINGDOM

Maidenhead (South)
Berkshire, SL6 7RJ
2, The Switchback
Gardner Road
Phone: +44 16 28778556
Fax: +44 16 28783811

Manchester (North)
M22 5WB
Manchester International Office Centre
Suite 3E (MIOC) Styal Road
Phone: +44 16 149934 34
Fax: +44 16 149934 74